




# SHP-30K-HV Series

## 30kW Industrial Standard Three-Phase HVDC Power System

- 3 $\psi$ 3-wire /  $\Delta$  or Y 340~530VAC or 3 $\psi$  4-wire / Y 340~530VAC
- High efficiency up to 97%
- Up to 120% peak power capability
- 2U high 19"-inch rack with forced air cooling
- Built-in CANBus/Optional PMBus/MODBus-RTU/RS-485 protocol
- Output voltage and constant current level programmable
- Active current sharing up to 12 units(285KW) and more
- Built-in remote ON-OFF control / Auxiliary power / Alarm signal / Fan fail
- Protections: Short circuit / Overload / Over voltage / Over temperature
- Double insulation for 55V model
- 5 years warranty

### Agriculture Machinery Charging Solution

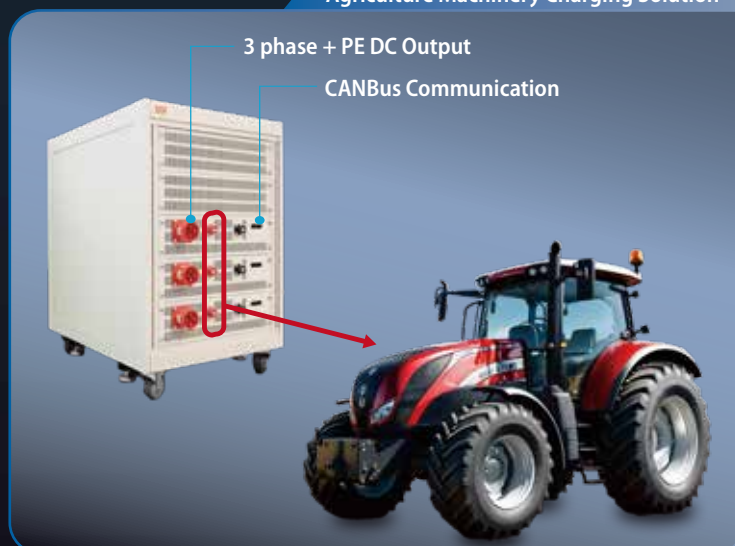

### HEADQUARTERS(Taiwan)

- [www.meanwell.com](http://www.meanwell.com)
- +886-2-2299-6100
- [info@meanwell.com](mailto:info@meanwell.com)

### MEAN WELL USA

- [www.meanwellusa.com](http://www.meanwellusa.com)
- +1-833-635-7201
- [info@meanwellusa.com](mailto:info@meanwellusa.com)

### MEAN WELL EUROPE

- [www.meanwell.eu](http://www.meanwell.eu)
- +31-20-758-6000
- [info@meanwell.eu](mailto:info@meanwell.eu)



SPEC.