

# Standard Power Solutions

 : The premium series  : The best cost-performance series

## Enclosed Type 15W~30KW



LRS(-N2)/SE/RS/  
RD/RT/RQ Series

High Cost Performance



UHP Series

Fanless



HRP(G)-N3 Series

3 Times Peak Power



NMP Series

Modular Power



HEP Series

Harsh Environments



RSP/RST/  
NSP/SHP Series

High Power

## DIN Rail Type 10W~960W



MDR Series

Class I Ultra-Slim



HDR Series

Class II Step-Shape



XDR/XTR Series

1 $\phi$ /3 $\phi$  Input  
Premium



XDR-E/SDR/  
NDR/EDR Series

1 $\phi$  Input  
High Cost Performance



WDR Series


180~550Vac  
Ultra Wide Input




DRC/DRS Series

Intelligent Security

## Open Frame Type 1W~600W

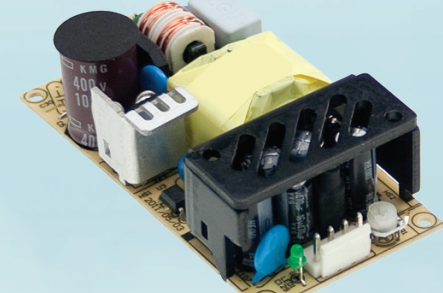


EPS/EPP/PSC  
Series

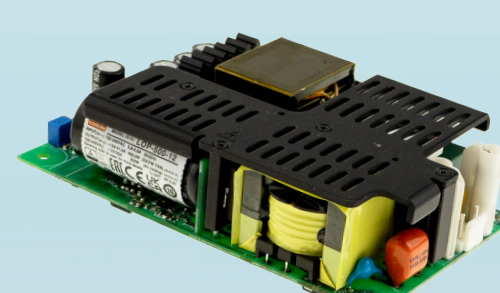

LOP Series



IRM/MPM/MFM  
Series

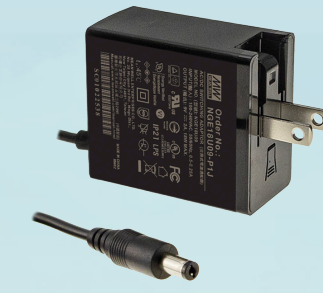

NGE Series

Wall-Mounted



GST/GSM Series

Desktop



OWA Series

Moisture-Proof

※ LOP-200~600 can replace EPP-100~500, and the next generation LOP is mainly recommended

## DC/DC Converter 0.5W~1000W



DDR/DDRH Series

ICT/PV/Railway



 
RSDH Series

PV Energy Storage





RSD Series

Railway



PSD Series

 ICT

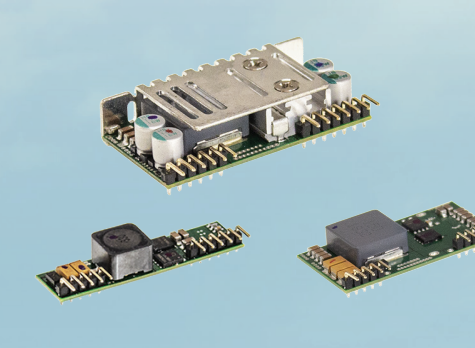

NSD/NID Series


ICT




Module Type

ICT/Medical/LED Lighting

## Charger / Inverter / VFD 30W~3200W

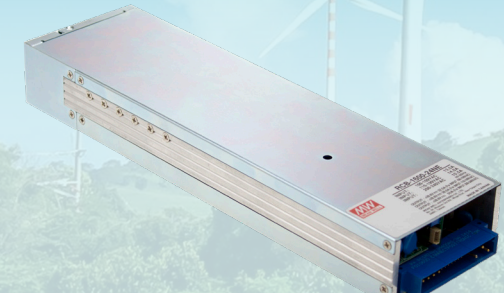


RPB/RCB/  
BIC/DBU Series

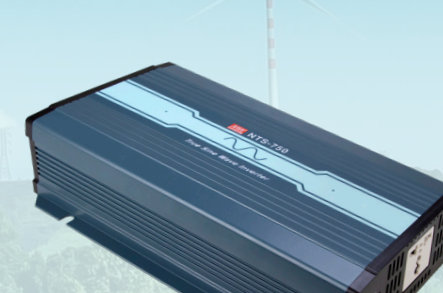

NTS/NTU Series



ENC Series

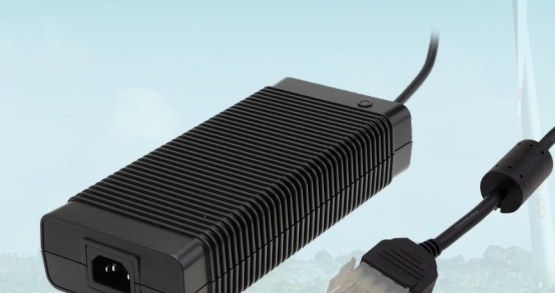

GC Series



VFD Series