



MEAN WELL Medical Power Supplies



NGE series 12-90W Interchangeable Wall Mount Adaptor



- Interchangeable AC plugs (EU, US, UK, AU, CN)
- Complies with multiple international certifications in various fields (ITE, Medical, Industrial and Household)
- Input range of 80~264 VAC, no-load standby power <0.075~1W
- Wide operating temp. range of -30~+70°C
- 3 years warranty




Note: Applying for plug safety regulations in South Korea and India

LOP series 200-600W Ultra Low Profile PCB Type PSU



- 4"x2" & 5"x3" ultra low profile dimensions (height: 25.4~33.5mm)
- 80~264VAC input and built-in PFC, no-load standby <0.5W
- Complies with multiple international certifications in various fields (ITE, Medical, Industrial and Household)
- Delivers 150% peak power for up to 3 seconds
- Operating temp. range of -30~+70°C
- Comply with 2xMOPP, suitable for Type BF medical applications
- Complies with OVCIII and operating altitude up to 5,000 meters
- 3 years warranty

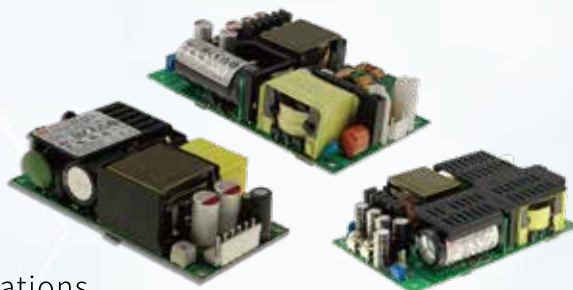

+886-2-22996100
www.meanwell.com



Virtual Expo